


PEMSA Wire Basket Tray Rapide

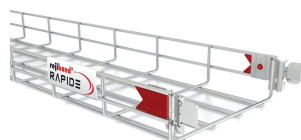

The PEMS A Wire Basket Tray is the backbone of PEMS A Wire Basket Tray System. Highly engineered features help ensure a secure installation that complies with industry codes and standards for high-performance cables. Clever design allows the installer to maximize field efficiency with the Rejiband Rapide Integrated Splice.

CERTIFICATIONS



FEATURES

Provides optimal support for high-performance low voltage and data cables

Innovative Rejiband Rapide installation system

IEC 61537 load rating and earthing compliant

Responsive design and layout services, including seismic

SPECIFICATIONS

Material: Carbon Steel

Finish: Electrogalvanized

Table 1/2

Catalog Number	Article Number	Длина мм (L)	Height (H)	Width (W)	A	Unit Weight
WBT100X100Q BG	823015	3000mm	100 mm	100 mm	32 mm	3.27 kg

CatalogNumber	Article Number	Длина мм (L)	Height (H)	Width (W)	A	Unit Weight
WBT100X100Q EG	823014	3000mm	100 mm	100 mm	32 mm	3.27 kg
WBT100X150Q BG	823025	3000mm	100 mm	150 mm	32 mm	3.45 kg
WBT100X150Q EG	823024	3000mm	100 mm	150 mm	32 mm	3.45 kg
WBT100X200Q BG	823035	3000mm	100 mm	200 mm	32 mm	4.14 kg
WBT100X200Q EG	823034	3000mm	100 mm	200 mm	32 mm	4.14 kg
WBT100X300Q BG	823045	3000mm	100 mm	300 mm	32 mm	6.15 kg
WBT100X300Q EG	823044	3000mm	100 mm	300 mm	32 mm	6.15 kg
WBT100X400Q BG	823055	3000mm	100 mm	400 mm	32 mm	7.23 kg
WBT100X400Q EG	823054	3000mm	100 mm	400 mm	32 mm	7.23 kg
WBT100X450Q BG	823085	3000mm	100 mm	450 mm	32 mm	7.44 kg
WBT100X450Q EG	823084	3000mm	100 mm	450 mm	32 mm	7.44 kg
WBT100X500Q BG	823065	3000mm	100 mm	500 mm	32 mm	8.34 kg
WBT100X500Q EG	823064	3000mm	100 mm	500 mm	32 mm	8.34 kg

CatalogNumber	Article Number	Длина мм (L)	Height (H)	Width (W)	A	Unit Weight
WBT100X600Q BG	823075	3000mm	100 mm	600 mm	32 mm	9.42 kg
WBT100X600Q EG	823074	3000mm	100 mm	600 mm	32 mm	9.42 kg
WBT60X100QB G	820015	3000mm	60 mm	100 mm	32 mm	2.43 kg
WBT60X100QE G	820014	3000mm	60 mm	100 mm	32 mm	2.43 kg
WBT60X150QB G	820025	3000mm	60 mm	150 mm	32 mm	2.6 kg
WBT60X150QE G	820024	3000mm	60 mm	150 mm	32 mm	2.6 kg
WBT60X200QB G	820035	3000mm	60 mm	200 mm	32 mm	3.33 kg
WBT60X200QE G	820034	3000mm	60 mm	200 mm	32 mm	3.33 kg
WBT60X300QB G	820045	3000mm	60 mm	300 mm	32 mm	5.13 kg
WBT60X300QE G	820044	3000mm	60 mm	300 mm	32 mm	5.13 kg
WBT60X400QB G	820055	3000mm	60 mm	400 mm	32 mm	6.21 kg
WBT60X400QE G	820054	3000mm	60 mm	400 mm	32 mm	6.21 kg
WBT60X450QB G	820085	3000mm	60 mm	450 mm	32 mm	6.39 kg

CatalogNumber	Article Number	Длина мм (L)	Height (H)	Width (W)	A	Unit Weight
WBT60X450QEG	820084	3000mm	60 mm	450 mm	32 mm	6.39 kg
WBT60X500QBG	820065	3000mm	60 mm	500 mm	32 mm	7.35 kg
WBT60X500QEG	820064	3000mm	60 mm	500 mm	32 mm	7.35 kg
WBT60X600QBG	820079	3000mm	60 mm	600 mm	32 mm	8.43 kg
WBT60X600QEG	820078	3000mm	60 mm	600 mm	32 mm	8.43 kg
WBT60X60QBG	820005	3000mm	60 mm	60 mm	32 mm	2.32 kg


Table 2/2

Catalog Number	Article Number	Color
WBT100X100QBG	823015	Черный
WBT100X100QEG	823014	Gray
WBT100X150QBG	823025	Черный
WBT100X150QEG	823024	Gray
WBT100X200QBG	823035	Черный
WBT100X200QEG	823034	Gray
WBT100X300QBG	823045	Черный
WBT100X300QEG	823044	Gray
WBT100X400QBG	823055	Черный

Catalog Number	Article Number	Color
WBT100X400QEG	823054	Gray
WBT100X450QBG	823085	Черный
WBT100X450QEG	823084	Gray
WBT100X500QBG	823065	Черный
WBT100X500QEG	823064	Gray
WBT100X600QBG	823075	Черный
WBT100X600QEG	823074	Gray
WBT60X100QBG	820015	Черный
WBT60X100QEG	820014	Gray
WBT60X150QBG	820025	Черный
WBT60X150QEG	820024	Gray
WBT60X200QBG	820035	Черный
WBT60X200QEG	820034	Gray
WBT60X300QBG	820045	Черный
WBT60X300QEG	820044	Gray
WBT60X400QBG	820055	Черный
WBT60X400QEG	820054	Gray
WBT60X450QBG	820085	Черный

Catalog Number	Article Number	Color
WBT60X450QEG	820084	Gray
WBT60X500QBG	820065	Черный
WBT60X500QEG	820064	Gray
WBT60X600QBG	820079	Черный
WBT60X600QEG	820078	Gray
WBT60X60QBG	820005	Черный

DIAGRAMS

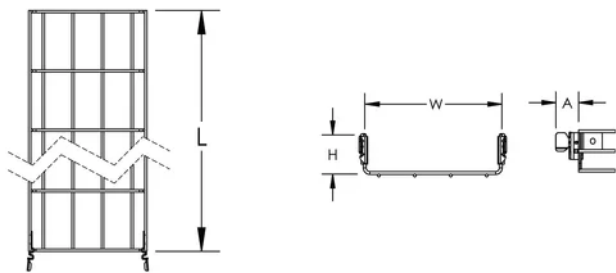

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

