

PEMSA Wire Basket Tray Splice Bar



CERTIFICATIONS



FEATURES

Added mechanical splice strength

Works with wide range of tray sizes and configurations

IEC 61537 load rating and earthing compliant

SPECIFICATIONS


Finish: Electrogalvanized

Material: Сталь

Table 1/1

Catalog Number	Article Number	Color	Длина мм (L)	Width (W)	Thickness (T)	Slot Size (SS)
WBTSPLBAR30 OEG	820704		300mm	22 mm	1.5 mm	7 x 28 mm
WBTSPLBAR30 OBG	820703	Черный	300mm	22 mm	1.5 mm	7 x 28 mm

DIAGRAMS

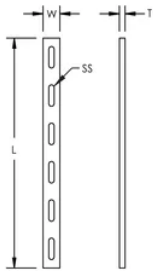

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

