

Rubber Profile for Strut Channel



FEATURES

EPDM insulation profile to prevent contact between support and ventilation duct

Suitable for strut

Can be used with threaded rods up to M10

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Temperature	Длина мм (L)	Height (H)	Width (W)
ISOSTRUT	335980	EPDM-SBR Rubber	-50 to 110 °C	20m	8 mm	42 mm

Table 2/2

Catalog Number	Article Number	Hole Size (HS)
ISOSTRUT	335980	11 mm

DIAGRAMS

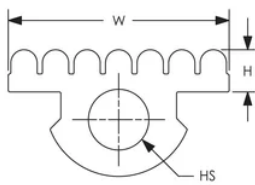

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

