

Strut Beam Clip



FEATURES

Beam Clip for clamping the open side of strut to a beam

Suitable for all strut channels

Requires installation in pairs

Structural attachment to beams to support nVent CADDY Eristrut

FM® Specification Tested

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Flange Thickness (FT)	Hole Size (HS)	Длина мм (L)
ZTA605	388080	Сталь	Hot-Dip Galvanized	16 mm Max	13 mm	49mm
ZT605HD	313260	Сталь	Hot-Dip Galvanized	16 mm Max	13 mm	49mm
ZTA605S6	387190	Stainless Steel 316 (EN 1.4401)		16 mm Max	13 mm	49mm

Table 2/2


Catalog Number	Article Number	Thickness (T)	Width (W)	Static Load	Screw Included
ZTA605	388080	6 mm	40 mm	2040N	Нет

Catalog Number	Article Number	Thickness (T)	Width (W)	Static Load	Screw Included
ZT605HD	313260	6 mm	40 mm	2040N	Да
ZTA605S6	387190	6 mm	40 mm	2040N	Нет

ADDITIONAL PRODUCT DETAILS

Indicated loads are based on installation with 1/2" (M12) hardware and strut channel type A.

DIAGRAMS

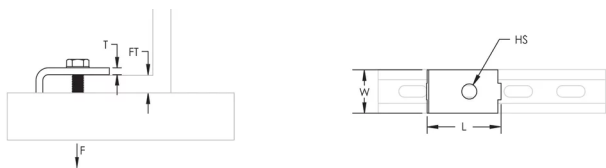

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

