

Uniklip Equal Tee



CERTIFICATIONS



FEATURES

Creates a quick and easy equal tee pathway intersection

Provides optimal support for high-performance low voltage and data cables

Innovative UNIKLIP installation system that installs up to three times faster

IEC 61537 load rating and earthing compliant

No field cutting or modifications required; just drop it in and keep installing the cable tray

Eliminates safety related concerns around field cutting

Tool-free, integrated couplers with Uniklip

SPECIFICATIONS

Finish: Pregalvanized


Material: Сталь

Table 1/1

Catalog Number	Article Number	Width (W)	Глубина мм (D)	Длина мм (L)	A	B
PCT50X050ET	850300	50 mm	49mm	375mm	202 mm	91 mm

CatalogNumber	Article Number	Width (W)	Глубина мм(D)	Длина мм (L)	A	B
PCT50X075ET	850310	75 mm	49mm	405mm	228 mm	91 mm
PCT50X100ET	850320	100 mm	49mm	425mm	253 mm	91 mm
PCT50X150ET	850330	150 mm	49mm	475mm	303 mm	91 mm
PCT50X225ET	850340	225 mm	49mm	550mm	378 mm	91 mm
PCT50X300ET	850350	300 mm	49mm	625mm	453 mm	91 mm
PCT50X450ET	850360	450 mm	49mm	775mm	603 mm	91 mm
PCT50X500ET	850370	500 mm	49mm	852mm	653 mm	91 mm
PCT50X600ET	850380	600 mm	49mm	925mm	753 mm	91 mm

DIAGRAMS

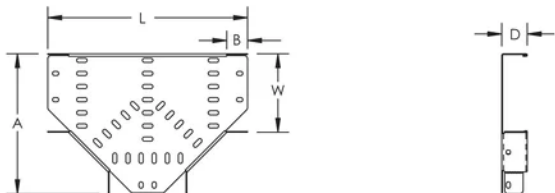

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

