


Комплект заземления/шин заземления для кольцевых наконечников, 1900 мм, высота 43 U

Data Solutions

CATALOG NUMBER

20118-863

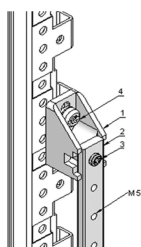

Медная шина обычно размещается внутри распределительного устройства, щитов управления и корпусов шинопроводов для заземления. Они также используются для подключения высоковольтного оборудования на электрических распределительных станциях и низковольтного оборудования в блоках аккумуляторов.

FEATURES

Для фиксации кабелей заземления с помощью кольцевых наконечников

Резьба в точке крепления M5, шаг отверстий 20 мм

Сборка, изолированная от рамы

Максимальная сила тока 200 А

Соединение 35 мм² с зажимом (принадлежность 21120-209)

PRODUCT ATTRIBUTES

Длина мм: 1900mm

Material: Copper

Package Quantity: 1

Product Type: Grounding Kit

Type: Ring Termination

Net Weight: 1.4kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE