
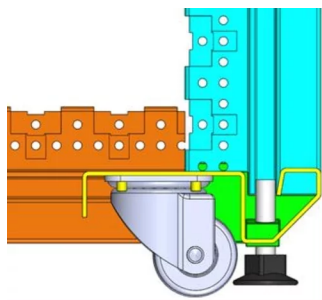
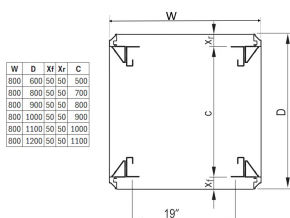


Подвижная рама для шкафа Varistar CP, 52 U, высота 2450, ширина 800, глубина 1000

Data Solutions

CATALOG NUMBER

20630-254

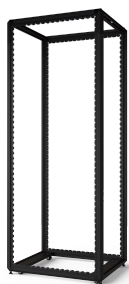

Сварная стальная рама Varistar для соответствия требованиям по статическим нагрузкам. Для интеграции 19-дюймовой, ETSI или монтажной панели. Для мобильного применения.

FEATURES

Сварная рама, с порошковым покрытием, цвет темно-серый, RAL 7021

PRODUCT ATTRIBUTES

Rack Height: 52U

Высота мм: 2450mm

Ширина мм: 800mm

Глубина мм: 1000mm

Package Quantity: 1

Color: Black Grey

Color Code: RAL 7021

Complies With: IEC 61587-1; IEC 61587-3

Dynamic Load: 1000kg

Frame Material: Сталь

Material: Сталь

Product Family: Varistar CP

Product Type: Cabinet/Rack Frame

Static Load: 1600kg

Type: Mobile

Works With: Varistar CP

Net Weight: 51.035kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE