


19-дюймовый монтажный профиль Varistar CP, RAL 7021, 47 U, высота 2200 мм

Data Solutions

CATALOG NUMBER

24630-014

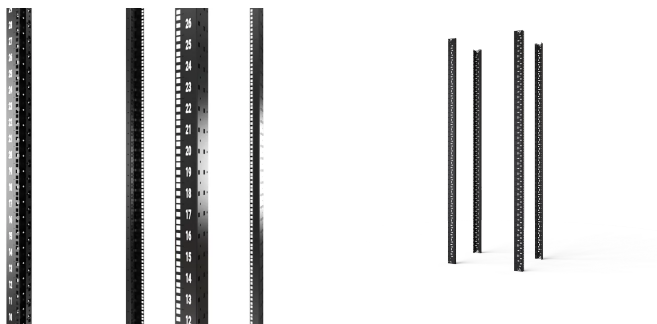

Крепление для направляющей с регулируемым шагом. В шкафах шириной 600 мм возможна сборка прямо на раму. При ширине 800 мм необходим кронштейн адаптера для уменьшенной ширины, для установки неполной высоты необходимы заглубляющие распорки.

FEATURES

19-дюймовый монтажный профиль с U-шкалой высоты

Установка по глубине определяется шагом 25 мм

В соответствии с IEC 60297-1 (DIN 41 494, часть 1)

PRODUCT ATTRIBUTES

Rack Height: 47U

Высота мм: 2200mm

Package Quantity: 4

Color: Jet Black

Color Code: RAL 9005

Finish: Powder Coated

Material: Сталь

Product Family: Varistar CP

Product Type: Slide Mount

Net Weight: 19.338kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE