


19-дюймовая передняя панель, высота 5 U, 3 мм, анодированный алюминий, необработанные кромки

Data Solutions

CATALOG NUMBER

30219-110

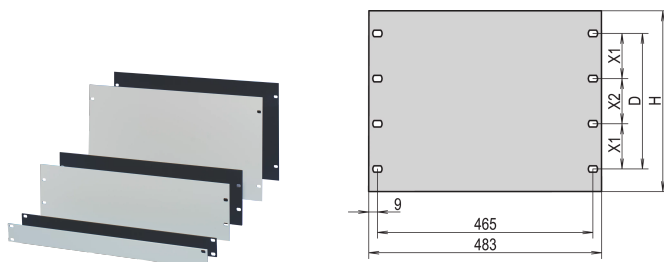

Передние панели выполнены из анодированного алюминия, цвет светло-серый (RAL 7035) или темно-серый (RAL 7021).

CERTIFICATIONS



FEATURES

Алюминий анодированный, 3 мм

PRODUCT ATTRIBUTES

Rack Height: 5U

Глубина мм (D): 3mm

Аксессуар Тип: Передняя панель

Mounting: Screw-on Front

Finish: Powder Coated

Front Finish: Anodized

Package Quantity: 1

Rear Finish: Anodized

Treated Edges: Нет

EMC Shielding: Нет

Высота мм (H): 221.4mm

Material: Алюминий

Product Type: Передняя панель

Rack Width: 95HP

Type: 19" Front Panel


Ширина мм (W): 483mm

Net Weight: 0.8kg

ADDITIONAL PRODUCT DETAILS

Монтажный комплект для сборки на 19 дюймов заказывается отдельно.

DIAGRAMS

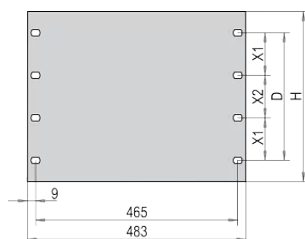

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE