


19-дюймовая передняя панель с отверстиями для ручек, высота 4 U, 3 мм, анодированная, необработанные кромки

Data Solutions

CATALOG NUMBER

30219-164

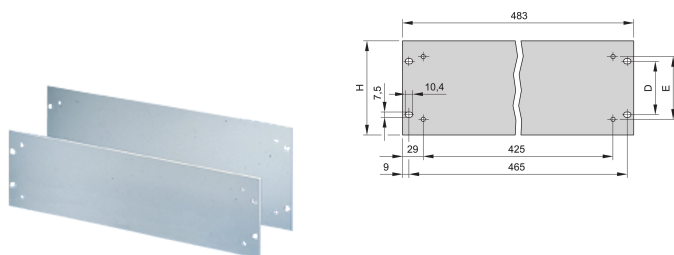

Оформите фасады и боковые границы устройств с помощью 19-дюймовых передних панелей SCHROFF. 19-дюймовые передние панели SCHROFF имеют дополнительные отверстия для крепления ручки и доступны в диапазоне от 1 U до 6 U.

CERTIFICATIONS



FEATURES

19" передние панели с дополнительными отверстиями для ручек

PRODUCT ATTRIBUTES

Rack Height: 4U

Глубина мм (D): 3mm

Аксессуар Тип: Передняя панель

Handle Type: Front Handle

Finish: Anodized

Mounting: Screw-on Front

Package Quantity: 1

Front Finish: Anodized

Rear Finish: Anodized

Treated Edges: Нет

EMC Shielding: Нет

Высота мм (H): 177mm

Material: Алюминий

Product Type: Передняя панель


Rack Width: 95HP

Type: 19" Front Panel

Ширина мм (W): 483mm

Net Weight: 0.664kg

DIAGRAMS

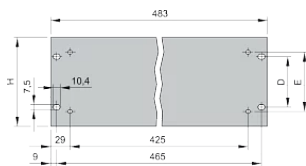

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE