


19-дюймовая передняя панель, 10 U, 4 мм, анодированный алюминий

Data Solutions

CATALOG NUMBER

40304-083

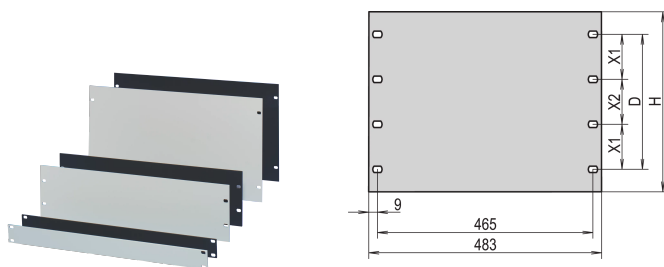

Передние панели выполнены из анодированного алюминия, цвет светло-серый (RAL 7035) или темно-серый (RAL 7021).

CERTIFICATIONS



FEATURES

Алюминий анодированный, 3 мм

PRODUCT ATTRIBUTES

Rack Height: 10U

Глубина мм (D): 4mm

Аксессуар Тип: Передняя панель

Mounting: Screw-on Front

Finish: Anodized

Front Finish: Anodized

Package Quantity: 1

Rear Finish: Anodized

Treated Edges: Да

EMC Shielding: Нет

Высота мм (H): 443.7mm

Material: Алюминий

Product Type: Передняя панель

Rack Width: 95HP

Type: 19" Front Panel


Ширина мм (W): 483mm

Net Weight: 2.36kg

ADDITIONAL PRODUCT DETAILS

Монтажный комплект для сборки на 19 дюймов заказывается отдельно.

DIAGRAMS

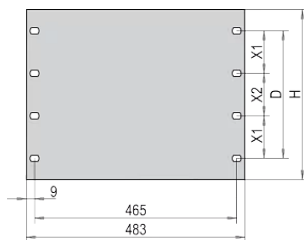

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE