

PEMSA Wire Basket Tray Center Support

Data Solutions



CERTIFICATIONS



FEATURES

Ideal for tray widths up to 200mm

Side load access for cable installation

IEC 61537 load rating and earthing compliant

SPECIFICATIONS

Finish: Electrogalvanized

Material: Сталь

Table 1/2


Catalog Number	Article Number	Color	Длина мм (L)	Width (W)	Height (H)	Hole Size (HS)
WBTCTRSPT M10	820420		59mm	35mm	5mm	8 – 10mm

CatalogNumber	Article Number	Color	Длина мм (L)	Width (W)	Height (H)	Hole Size (HS)
WBTCTRSPT M10BG	820421	Черный	59mm	35mm	5mm	8 – 10mm
WBTCTRSPT M6	820400		59mm	35mm	5mm	6mm

Table 2/2

Catalog Number	Article Number	Certifications
WBTCTRSPTM10	820420	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT QC
WBTCTRSPTM10BG	820421	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT QC
WBTCTRSPTM6	820400	CE, CADDY EU WBT QC

DIAGRAMS

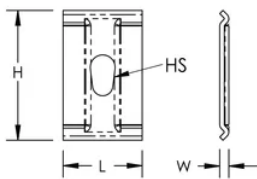

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE