

PEMSA Wire Basket Tray Splice Bar

Data Solutions



CERTIFICATIONS



FEATURES

Added mechanical splice strength

Works with wide range of tray sizes and configurations

IEC 61537 load rating and earthing compliant

SPECIFICATIONS

Finish: Electrogalvanized


Material: Сталь

Table 1/1

Catalog Number	Article Number	Color	Длина мм (L)	Width (W)	Thickness (T)	Slot Size (SS)
WBTSPBAR30 OBG	820703	Черный	300mm	22mm	1.5mm	7 x 28 mm

CatalogNumber	Article Number	Color	Длина мм (L)	Width (W)	Thickness (T)	Slot Size (SS)
WBTSPBAR30 0EG	820704		300mm	22mm	1.5mm	7 x 28 mm

DIAGRAMS

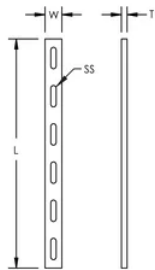

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE