

Ground Rod Driver



FEATURES

Usable on all types of round ground rods: copper-bonded, galvanized, and stainless steel

Inserts are interchangeable with standard ground rod driver body


The driver will not deform the end of the rod, making connection of the ground conductor quick and easy

SPECIFICATIONS

Table 1/1

Catalog Number	Article Number	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Длина мм (L)	Unit Weight
EGRD34	158520	3/4" Max	17.2 mm Max	1500mm	10.4 kg
EGRD58	158500	5/8" Max	14.2 mm Max	1500mm	10.4 kg

DIAGRAMS

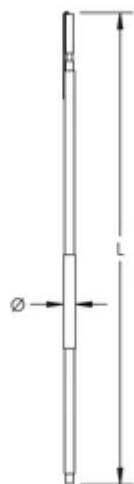

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE