


ISONV Fixed Offset Mast Bracket

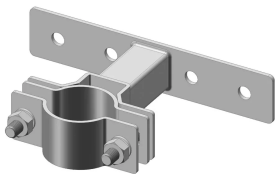

FEATURES

Use for cantilevered mounting ISONV masts

SPECIFICATIONS

Material: Stainless Steel 304 (EN 1.4301)


Table 1/2

Catalog Number	Длина мм (L)	A	B	Height (H)	Hole Size (HS)	Width (W)
ISONVBKT80	80mm	45 mm	158 mm	40 mm	11 mm	208 mm
ISONVBKT200	200mm	45 mm	158 mm	40 mm	11 mm	208 mm
ISONVBKT15	15mm	45 mm	158 mm	40 mm	11 mm	198 mm

Table 2/2

Catalog Number	Diameter (Ø)
ISONVBKT80	40 - 50 mm
ISONVBKT200	40 - 50 mm
ISONVBKT15	40 - 50 mm

DIAGRAMS

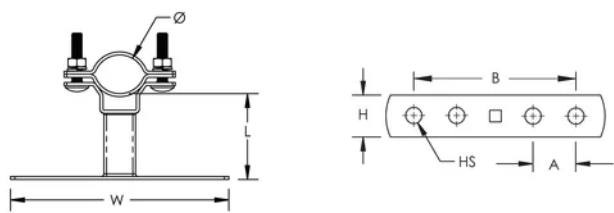

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE