


Joint Bond Mold Pair with Mounting Parts and Clips, Signal

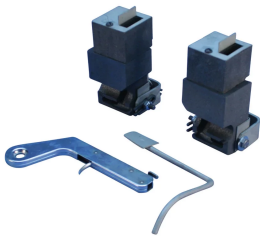

FEATURES

Pair of replacement molds with mounting parts designed for the installation of jumper bonds to the head of the rail

Connection is made within the confines of the splice bar

Includes mold cleaner and flint ignitor

SPECIFICATIONS

Rail Type: 85 lb to 141 lb T-Rail Sections

Product: Mold, frames, and clips

Table 1/1

Catalog Number	Article Number	Material	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
SBM456F		Сталь, Graphite	3/4" XS	3/16" Bondstrand	4.76mm	T6, T7
SBS925F		Сталь, Graphite	Head Free	3/16" Bondstrand	4.76mm	T6, T7
SBS5838F	165171	Сталь, Graphite	3/4" Tab	3/16" Bondstrand	4.76mm	T6, T7
SBS898F		Сталь, Graphite	1" Tab	5/16" Bondstrand	7.94mm	T6, T7

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE