

FS Spacer Clamp



CERTIFICATIONS



FEATURES

Provides support for nVent ERIFLEX Flexibar and insulated braided conductors without damaging the insulation

Ensures correct spacing for optimum cooling

Supports up to four conductors in parallel

Easy to install

Spacers are halogen free

RoHS compliant

SPECIFICATIONS

Finish: Electrogalvanized

Flammability Rating: UL® 94HB

Working Temperature: -40 to 130 °C

Table 1/2

Catalog Number	Article Number	Material	Conductor Width	Height (H)	Длина мм (L)	Hole Size (HS)
FS40-63	553570	Сталь, Polyamide	40 - 63 mm	95 mm	166mm	8.5 mm

CatalogNumber	Article Number	Material	Conductor Width	Height (H)	Длина мм (L)	Hole Size (HS)
FS80-100	553580	Сталь, Polyamide	80 - 100 mm	140 mm	224mm	8.5 mm


Table 2/2

Catalog Number	Article Number	A	Unit Weight
FS40-63	553570	150 mm	0.1 kg
FS80-100	553580	200 mm	0.25 kg

ADDITIONAL PRODUCT DETAILS

Recommended distance between supports is 400 mm (15 3/4").

DIAGRAMS

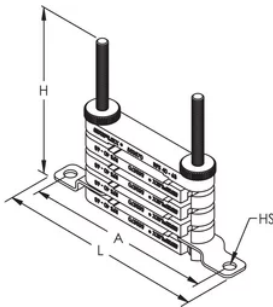

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE