


nVent ERIFLEX Flexibar Small Bending and Folding Tool

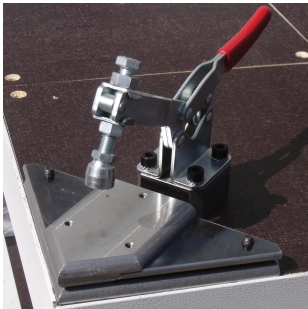

CERTIFICATIONS



FEATURES

Used to ease the process of bending, folding or twisting of nVent ERIFLEX Flexibar

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Conductor Thickness	Conductor Width	Глубина мм	Height	Width
SFBF	558945	5 mm	32 mm Max	360mm	160 mm	360 mm

Table 2/2

Catalog Number	Article Number	Unit Weight
SFBF	558945	5.11 kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE