


, WO60

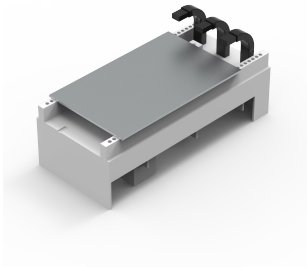

Busbar adapters adapted to the component manufacturers' design.

FEATURES

Description: 3-pole busbar adapter 160 A, adapted to the component manufacturer's design.

Rated voltage: 690 V

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 7.7 W

Pack quantity: 1 pc.

SPECIFICATIONS

Table 1/1						
Catalog Number	Высота мм	Ширина мм	Глубина мм	Material	Finish	Color
32575	200mm	90mm	69mm	Plastic, Mild Steel	Plated	Черный, Light Gray
32660	200mm	76mm	69mm	Plastic, Mild Steel	Plated	Черный, Light Gray

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE