


, WO60

Universal busbar adapter, with one adjustable mounting rail and with spring terminals 1.5-6 mm².

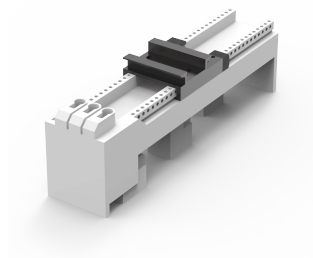

FEATURES

Description: Busbar adapter 32 A. With one adjustable mounting rail. Without cables, with spring terminals 1.5 - 6 mm².

Rated voltage: 690 V

Rated current: 32 A

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 1.6 W

Poles: 3-pole

Pack quantity: 1 pcs.

SPECIFICATIONS

Table 1/1						
Catalog Number	Высота мм	Ширина мм	Глубина мм	Material	Finish	Color
32486	200mm	45mm	63mm	Plastic, Mild Steel	Plated	Черный, Light Gray

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE