


, WO60

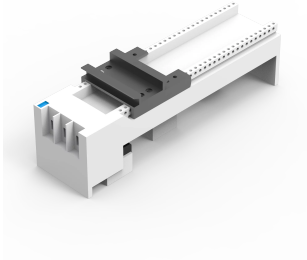

Busbar adapter with one mounting rail with screw terminals 16 mm².

INDUSTRY STANDARDS

UL

CSA

GL

FEATURES

Approvals: CSA, UL, GL

Poles: 3-pole

Power dissipation at 80% load: 6 W

For busbars: 12, 15, 20, 25, 30 × 5, 10

Rated current: 80 A

Rated voltage: 690 V

Pack quantity: 1 pc.

Description: Busbar adapter 80 A. With one adjustable mounting rail. With terminals 16 mm², operated from the back.

SPECIFICATIONS

Table 1/1						
Catalog Number	Высота мм	Ширина мм	Глубина мм	Material	Finish	Color
32466	200mm	54mm	63mm	Plastic, Mild Steel	Plated	Черный, Light Gray
32469	200mm	72mm	63mm	Plastic, Mild Steel	Plated	Черный, Light Gray

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE