

B-Series Vertical Filler Material Kit



B-Series vertical filler material kits contain the following: Filler material, vertical packing, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

FEATURES

Simplifies ordering

All components are for one-time use

SPECIFICATIONS

Table 1/1

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Package Quantity
RBB992B	28 mm	#9	30M	1
RBB1092B	32 mm	#10		1
RBB8101B	25 mm	#8	25M	1
RBB792B	22 mm	#7		1
RBB692B	20 mm	#6	20M	1
RBB11101B	36 mm	#11	35M	1
RBB592B	16 mm	#5	15M	1
RBB1892B	57 mm	#18	55M	1

Catalog Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Package Quantity
RBB1292B	38 mm	#12		1
RBB14101B	43 mm	#14	45M	1

ADDITIONAL PRODUCT DETAILS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Packing, (3) Pouring Basin Ceramic Guide Tube, and (4) Pouring Basin Ceramic Insert and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBB592B	RBF40	RBS35477	RBS5037	RBS5038
RBB692B	RBF40	RBS35477	RBS5037	RBS5038
RBB792B	RBF50	RBS35478	RBS5037	RBS5038
RBB8101B	RBF55	RBS354710	RBS5037	RBS5038
RBB992B	RBF80	RBS354711	RBS5037	RBS5038
RBB1092B	RBF90	RBS354712	RBS5037	RBS5038
RBB11101B	RBF105	RBS354712	RBS5037	RBS5038
RBB1292B	RBF125	RBS354715	RBS5037	RBS5038
RBB14101B	RBF180	RBS354715	RBS5037	RBS5039
RBB1892B	RBF220	RBS354720	RBS5037	RBS5039

DIAGRAMS

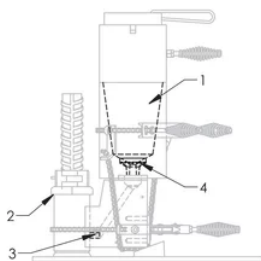

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE