


CFF Tapered Screw-In Plug for A12, A22 and A32K Couplers

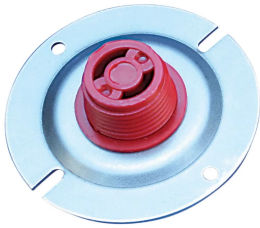

FEATURES

Designed for use with the A12, A22 and A32K coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)
EL36CFF	153925	High Density Polyethylene (HDPE), Сталь	36 mm	#11	35M	95 mm
EL28CFF	153900	High Density Polyethylene (HDPE), Сталь	28 mm	#9	30M	75 mm
EL22CFF	153880	High Density Polyethylene (HDPE), Сталь	22 mm	#7		75 mm
EL32CFF	153920	High Density Polyethylene (HDPE), Сталь	32 mm	#10		95 mm

CatalogNumber	Article Number	Material	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)
EL25CFF	153890	High Density Polyethylene (HDPE), Сталь	25 mm	#8	25M	75 mm
EL40CFF	153930	High Density Polyethylene (HDPE), Сталь	40 mm			95 mm
EL50CFF	154980	High Density Polyethylene (HDPE), Сталь	50 mm			95 mm
EL30CFF	153910	High Density Polyethylene (HDPE), Сталь	30 mm			75 mm

Table 2/2

Catalog Number	Article Number	Height (H)	Color
EL36CFF	153925	18 mm	Blue
EL28CFF	153900	18 mm	Черный
EL22CFF	153880	18 mm	Blue
EL32CFF	153920	18 mm	Yellow
EL25CFF	153890	18 mm	Красный
EL40CFF	153930	18 mm	Зеленый
EL50CFF	154980	18 mm	Черный
EL30CFF	153910	18 mm	White

DIAGRAMS

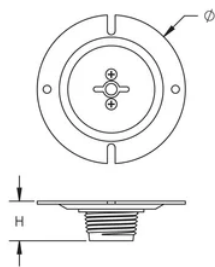

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE