 


PFF Parallel Plastic Screw-In Plug for P13/P14 Couplers, European Design



The European Design Version (Suffix EE) is currently being phased out. All future projects should be designed with the Worldwide Design Version (Suffixes N and LN). This change is being done in order to simplify our product offering and eliminate redundant designs. Please contact Customer Care or your local Sales Engineer/Manager if you require more information on this transition.

FEATURES

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

SPECIFICATIONS

Design Version: European (Specialty Materials)

Table 1/2


Catalog Number	Article Number	Material	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)
EL1416PFF	153810	High Density Polyethylene (HDPE), Сталь	14 mm, 16 mm	#5	15M	65 mm
EL1012PFF	153800	High Density Polyethylene (HDPE), Сталь	10 mm, 12 mm	#3, #4	10M	65 mm
EL2225PFF	153840	High Density Polyethylene (HDPE), Сталь	22 mm, 25 mm	#7, #8	25M	95 mm

CatalogNumber	Article Number	Material	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)
EL2830PFF	153850	High Density Polyethylene (HDPE), Сталь	28 mm, 30 mm	#9	30M	95 mm
EL20PFF	153830	High Density Polyethylene (HDPE), Сталь	20 mm	#6	20M	75 mm
EL18PFF	153820	High Density Polyethylene (HDPE), Сталь	18 mm			75 mm
EL32PFF	153860	High Density Polyethylene (HDPE), Сталь	32 mm	#10		95 mm
EL40PFF	153870	High Density Polyethylene (HDPE), Сталь	40 mm			95 mm

Table 2/2

Catalog Number	Article Number	Height (H)	Color
EL1416PFF	153810	15 mm	Черный
EL1012PFF	153800	15 mm	Красный
EL2225PFF	153840	18 mm	Красный
EL2830PFF	153850	18 mm	Черный
EL20PFF	153830	18 mm	Yellow
EL18PFF	153820	18 mm	White
EL32PFF	153860	18 mm	Yellow
EL40PFF	153870	18 mm	Зеленый

DIAGRAMS

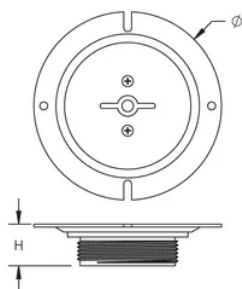

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE