

19-дюймовая передняя панель



Передние панели выполнены из анодированного алюминия, цвет светло-серый (RAL 7035) или темно-серый (RAL 7021).

CERTIFICATIONS



FEATURES

Алюминий анодированный, 3 мм

SPECIFICATIONS

Rack Width:	95HP
Material:	Алюминий
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель

Table 1/3

Catalog Number	Rack Height	Глубина мм (D)	Mounting	Finish	Front Finish	Package Quantity
30219-098	1U	3mm	Screw-on Front	Anodized	Anodized	1
30118-948	1U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-299	1U	3mm	Screw-on Front	Powder Coated	Painted	1

CatalogNumber	Rack Height	Глубина мм(D)	Mounting	Finish	Front Finish	Package Quantity
40304-074	1U	4mm	Screw-on Front	Anodized	Anodized	1
30219-101	2U	3mm	Screw-on Front	Anodized	Anodized	1
30118-301	2U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-949	2U	3mm	Screw-on Front	Powder Coated	Painted	1
40304-075	2U	4mm	Screw-on Front	Anodized	Anodized	1
30219-104	3U	3mm	Screw-on Front	Anodized	Anodized	1
30118-302	3U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-950	3U	3mm	Screw-on Front	Powder Coated	Painted	1
40304-076	3U	4mm	Screw-on Front	Anodized	Anodized	1
30219-107	4U	3mm	Screw-on Front	Anodized	Anodized	1
30118-303	4U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-951	4U	3mm	Screw-on Front	Powder Coated	Painted	1
30219-110	5U	3mm	Screw-on Front	Powder Coated	Anodized	1
30118-304	5U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-952	5U	3mm	Screw-on Front	Powder Coated	Painted	1
40304-077	4U	4mm	Screw-on Front	Anodized	Anodized	1
30118-953	6U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-305	6U	3mm	Screw-on Front	Powder Coated	Painted	1

CatalogNumber	Rack Height	Глубина мм(D)	Mounting	Finish	Front Finish	Package Quantity
30219-113	6U	3mm	Screw-on Front	Anodized	Anodized	1
40304-079	6U	4mm	Screw-on Front	Anodized	Anodized	1
30118-954	7U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-306	7U	3mm	Screw-on Front	Powder Coated	Painted	1
30219-137	7U	3mm	Screw-on Front	Anodized	Anodized	1
40304-080	7U	4mm	Screw-on Front	Anodized	Anodized	1
30118-956	9U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-308	9U	3mm	Screw-on Front	Powder Coated	Painted	1
30219-143	9U	3mm	Screw-on Front	Anodized	Anodized	1
40304-082	9U	4mm	Screw-on Front	Anodized	Anodized	1
30118-307	8U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-309	10U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-955	8U	3mm	Screw-on Front	Powder Coated	Painted	1
30118-957	10U	3mm	Screw-on Front	Powder Coated	Painted	1
30219-138	8U	3mm	Screw-on Front	Anodized	Anodized	1
30219-144	10U	3mm	Screw-on Front	Anodized	Anodized	1
40304-078	5U	4mm	Screw-on Front	Anodized	Anodized	1
40304-081	8U	4mm	Screw-on Front	Anodized	Anodized	1

CatalogNumber	Rack Height	Глубина мм(D)	Mounting	Finish	Front Finish	Package Quantity
40304-083	10U	4mm	Screw-on Front	Anodized	Anodized	1

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Color Code	EMC Shielding	Высота мм (H)	Type
30219-098	Anodized	Нет		Нет	43.6mm	19" Front Panel
30118-948	Painted		RAL 7021	Нет	43.6mm	19" Front Panel
30118-299	Painted		RAL 7035	Нет	43.6mm	19" Front Panel
40304-074	Anodized	Да		Нет	43.6mm	19" Front Panel
30219-101	Anodized	Нет		Нет	88.1mm	19" Front Panel
30118-301	Painted		RAL 7035	Нет	88.1mm	19" Front Panel
30118-949	Painted		RAL 7021	Нет	88.1mm	19" Front Panel
40304-075	Anodized	Да		Нет	88.1mm	19" Front Panel
30219-104	Anodized	Нет		Нет	132.5mm	19" Front Panel
30118-302	Painted		RAL 7035	Нет	132.5mm	19" Front Panel
30118-950	Painted		RAL 7021	Нет	132.5mm	19" Front Panel
40304-076	Anodized	Да		Нет	132.5mm	19" Front Panel
30219-107	Anodized	Нет		Нет	177mm	19" Front Panel
30118-303	Painted		RAL 7035	Нет	177mm	19" Front Panel
30118-951	Painted		RAL 7021	Нет	177mm	19" Front Panel

CatalogNumber	Rear Finish	Treated Edges	Color Code	EMC Shielding	Высота мм (H)	Type
30219-110	Anodized	Нет		Нет	221.4mm	19" Front Panel
30118-304	Painted		RAL 7035	Нет	221.4mm	19" Front Panel
30118-952	Painted		RAL 7021	Нет	221.4mm	19" Front Panel
40304-077	Anodized	Да		Нет	177mm	19" Front Panel
30118-953	Painted		RAL 7021	Нет	265.9mm	19" Front Panel
30118-305	Painted		RAL 7035	Нет	265.9mm	19" Front Panel
30219-113	Anodized	Нет		Нет	265.9mm	19" Front Panel
40304-079	Anodized	Да		Нет	265.9mm	19" Front Panel
30118-954	Painted		RAL 7021	Нет	310.3mm	19" Front Panel
30118-306	Painted		RAL 7035	Нет	310.3mm	19" Front Panel
30219-137	Anodized	Нет		Нет	310.3mm	19" Front Panel
40304-080	Anodized	Да		Нет	310.3mm	19" Front Panel
30118-956	Painted		RAL 7021	Нет	399.2mm	19" Front Panel
30118-308	Painted		RAL 7035	Нет	399.2mm	19" Front Panel
30219-143	Anodized	Нет		Нет	399.2mm	19" Front Panel
40304-082	Anodized	Да		Нет	399.2mm	19" Front Panel
30118-307	Painted		RAL 7035	Нет	354.8mm	19" Front Panel
30118-309	Painted		RAL 7035	Нет	443.7mm	19" Front Panel

CatalogNumber	Rear Finish	Treated Edges	Color Code	EMC Shielding	Высота мм (H)	Type
30118-955	Painted		RAL 7021	Нет	354.8mm	19" Front Panel
30118-957	Painted		RAL 7021	Нет	443.7mm	19" Front Panel
30219-138	Anodized	Нет		Нет	354.8mm	19" Front Panel
30219-144	Anodized	Нет		Нет	443.7mm	19" Front Panel
40304-078	Anodized	Да		Нет	221.4mm	19" Front Panel
40304-081	Anodized	Да		Нет	354.8mm	19" Front Panel
40304-083	Anodized	Да		Нет	443.7mm	19" Front Panel

Table 3/3

Catalog Number	Ширина мм (W)	Quick Ship
30219-098	483mm	No
30118-948	483mm	No
30118-299	483mm	No
40304-074	483mm	No
30219-101	483mm	No
30118-301	483mm	No
30118-949	483mm	No
40304-075	483mm	No
30219-104	483mm	No
30118-302	483mm	No


Catalog Number	Ширина мм (W)	Quick Ship
30118-950	483mm	No
40304-076	483mm	No
30219-107	483mm	No
30118-303	483mm	No
30118-951	483mm	No
30219-110	483mm	No
30118-304	483mm	No
30118-952	483mm	No
40304-077	483mm	No
30118-953	483mm	No
30118-305	483mm	No
30219-113	483mm	No
40304-079	483mm	No
30118-954	483mm	No
30118-306	483mm	No
30219-137	483mm	No
40304-080	483mm	No
30118-956	483mm	No

Catalog Number	Ширина мм (W)	Quick Ship
30118-308	483mm	No
30219-143	483mm	No
40304-082	483mm	No
30118-307	483mm	No
30118-309	483mm	No
30118-955	483mm	No
30118-957	483mm	No
30219-138	483mm	No
30219-144	483mm	No
40304-078	483mm	No
40304-081	483mm	No
40304-083	483mm	No

ADDITIONAL PRODUCT DETAILS

Монтажный комплект для сборки на 19 дюймов заказывается отдельно.

DIAGRAMS

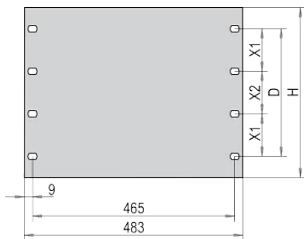

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE