


Передняя панель АТСА, Алюминиевый профиль, Reinforced With Spring Loading

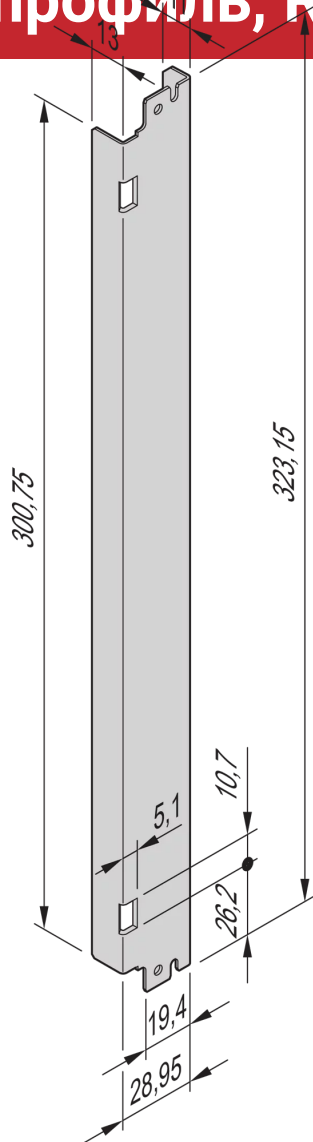

Передняя панель AdvancedTCA для подпружиненной ручки IEA с литым наконечником.

CERTIFICATIONS



FEATURES

Конфигурация: Передняя панель с ручкой IEA (с подпружиниванием или без него)

Алюминиевый профиль; для ЭМС-уплотнителя из сетки

SPECIFICATIONS

Глубина мм (D): 1mm

Rack Width: 6HP

Rack Height: 8U

Material: Алюминий


Аксессуар Тип: Передняя панель

Product Type: Передняя панель

Table 1/2						
Catalog Number	Package Quantity	Handle Type	Front Finish	Rear Finish	Finish	Высота мм (H)
31596-900	1	Lever	Raw	Raw	Passivated	323.15mm
31596-899	1	Plunger	Raw	Raw	Passivated	323.15mm

Table 2/2		
Catalog Number	Ширина мм (W)	Quick Ship
31596-900	29mm	No
31596-899	29mm	No

DIAGRAMS

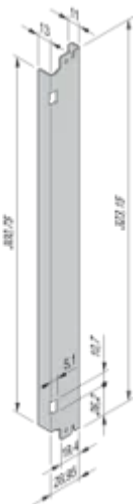

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE