


Комплект монтажных профилей/панелей 19 дюйм./23 дюйм. для Comline ECL

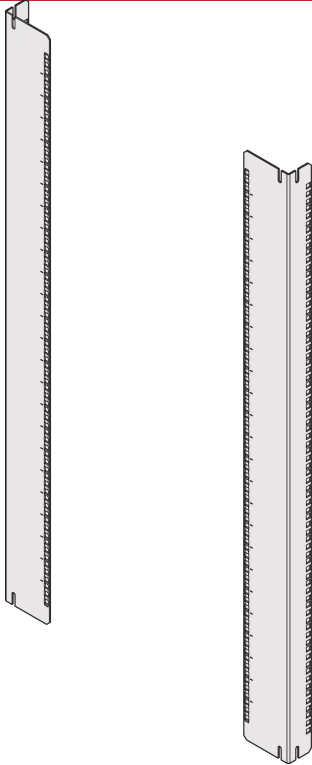

Комплект для монтажа на панель/профиль на 19/23 дюймов Comline ECL с максимальной нагрузкой 400 кг, обеспечивает удобство крепления на заглубляющих распорках.

CERTIFICATIONS



FEATURES

Комплект монтажных профилей/панелей 19 дюйм./23 дюйм. для Comline ECL

Для установки на заглубляющих распорках (шаг 25 мм)

Допустимая нагрузка 400 кг

Возможность установки направляющих реек

Для углубленного монтажа 19/23-дюймовых компонентов

SPECIFICATIONS

Product Type: Slide Mount
Material: Сталь

Table 1/1					
Catalog Number	Rack Height	Высота мм	Ширина мм	Package Quantity	Quick Ship
22349-027	25U	1220mm	700mm	2	No
22349-024	12U	660mm	600mm	2	No
22349-026	18U	900mm	700mm	2	No
22349-025	18U	900mm	600mm	2	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE