


ВИНТ С ПОТАЙНОЙ ГОЛОВКОЙ

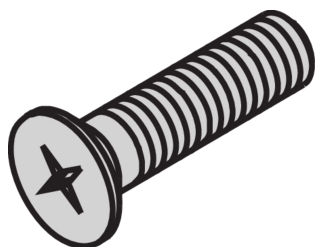

Винты с потайной головкой используются для многих вариантов монтажа в блочном каркасе или настольном корпусе.

CERTIFICATIONS



FEATURES

Винт с потайной головкой

SPECIFICATIONS

Product Type: Screw

Table 1/2

Catalog Number	Длина мм	Material	Finish	Package Quantity	Thread Size	Высота мм
24560-182	12mm	Сталь	Zinc Plated	4	M5	
24560-158	7.7mm	Сталь	Zinc Plated	100	M2.5	
21100-429	8mm	Сталь	Nickel Plated	100	M2.5	
21100-507	12mm	Сталь	Nickel Plated	100	M2.5	
21100-500	10mm	Сталь	Nickel Plated	100	M2.5	

CatalogNumber	Длина мм	Material	Finish	Package Quantity	Thread Size	Высота мм
21100-649	10mm	Сталь	Zinc Plated	100	M2.5	
21100-542	8mm	Сталь	Nickel Plated	100	M3	
24560-139	5mm	Сталь	Zinc Plated	100	M4	
24560-145	14mm	Сталь	Zinc Plated	100	M4	
24560-183	12mm	Сталь	Zinc Plated	100	M5	
24560-164	8mm	Сталь	Nickel Plated	100	M2.5	4.7mm

Table 2/2

Catalog Number	Type	Ширина мм	Works With	Thread Type	Torque	Quick Ship
24560-182	Countersunk Screw		Передние панели		2.4N·m	No
24560-158	Countersunk Screw		Передние панели			No
21100-429	Screw		Передние панели			No
21100-507	Screw		Передние панели			No
21100-500	Screw		Передние панели			No
21100-649	Screw		Передние панели			No
21100-542	Screw		Передние панели			No
24560-139	Countersunk Screw		Передние панели		1.3N·m	No
24560-145	Countersunk Screw		Передние панели		2.4N·m	No
24560-183	Countersunk Screw		Передние панели		2.4N·m	No

CatalogNumber	Type	Ширина мм	Works With	Thread Type	Torque	Quick Ship
24560-164	Countersunk Screw	4.7mm	Передние панели	Metric		No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE