


Объединительная плата CPCI

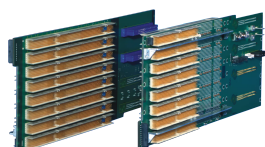

Объединительные платы nVent SCHROFF CompactPCI имеют лучшие в своем классе показатели целостности сигнала и наработки на отказ благодаря SMD-компонентам, керамическим конденсаторам и разъемам с тугой посадкой.

CERTIFICATIONS



FEATURES

Цифровое заземление может быть подключено / изолировано от заземления шасси с помощью винтов.

Параметр V(I/O) можно установить на +3,3 V или +5 V

Внешние слои действуют как заземляющие поверхности

Utility-штекер для сигналов состояния (SMCQ)

Превосходное подавление высокочастотных помех и очень высокие значения среднего времени наработки на отказ благодаря керамическим конденсаторам

Соединитель шины управления интеллектуальными платформами (IPMB) по спецификации PICMG 2.9

Соединения для Intelligent Platform Management Bus (IPMB) по PICMG 2.9

SPECIFICATIONS

Table 1/3

Catalog Number	Product Type	Number of Slots	Rack Height	Backplane Type	System Slot	Slot Width
23006-792	Объединительная плата	2	7U	CompactPCI, 64-bit	Left	4HP

CatalogNumber	Product Type	Number ofSlots	Rack Height	BackplaneType	System Slot	Slot Width
23006-793	Объединительная плата	2	7U	CompactPCI, 64-bit	Left	4HP
23006-794	Объединительная плата	2	9U	CompactPCI, 64-bit	Left	4HP
23006-799	Объединительная плата	4	7U	CompactPCI, 64-bit	Left	4HP
23006-798	Объединительная плата	6	7U	CompactPCI, 64-bit	Left	4HP
23006-601	Объединительная плата	8	6U	CompactPCI, 64-bit, H.110 Bus	Right	4HP
23006-611	Объединительная плата	8	9U	CompactPCI, 64-bit, PSB, H.110 Bus	Left	4HP
23006-795	Объединительная плата	4	7U	CompactPCI, 64-bit	Left	4HP
23006-796	Объединительная плата	6	9U	CompactPCI, 64-bit	Left	4HP
23006-797	Объединительная плата	8	9U	CompactPCI, 64-bit	Left	4HP

Table 2/3

Catalog Number	Voltage I/O	Connector Type	Power Connector Type	Utility Connector Type	Ширина мм	Package Quantity
23006-792	5V	HM 2.0	ATX (male) Connector		39.64mm	1
23006-793	5V	HM 2.0	Mini-fit 10-pin	SMCQ, 12-pin	39.64mm	1
23006-794	5V	HM 2.0	(1) P47	SMCQ, 12-pin	39.64mm	1
23006-799	5V	HM 2.0	Mini-fit 24-pin	SMCQ, 12-pin		1
23006-798	5V	HM 2.0	Mini-fit 24-pin	SMCQ, 12-pin	121mm	1
23006-601	5V	HM 2.0	Power Bugs for M4 Cable Lugs	SMCQ, 12-pin	161.56mm	1
23006-611	5V	HM 2.0	(2) P47	SMCQ, 12-pin	161.56mm	1

CatalogNumber	Voltage I/O	ConnectorType	Power ConnectorType	Utility ConnectorType	Ширина мм	Package Quantity
23006-795	5V	HM 2.0	(2) P47	SMCQ, 12-pin		1
23006-796	5V	HM 2.0	(2) P47	SMCQ, 12-pin	121mm	1
23006-797	5V	HM 2.0	(2) P47	SMCQ, 12-pin	161.56mm	1

Table 3/3

Catalog Number	Quick Ship
23006-792	No
23006-793	No
23006-794	No
23006-799	No
23006-798	No
23006-601	No
23006-611	No
23006-795	No
23006-796	No
23006-797	No

ADDITIONAL PRODUCT DETAILS

Другие конфигурации доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE