


VME64x System, Tower, 5 U, Pluggable PSU

CATALOG NUMBER

10836-045

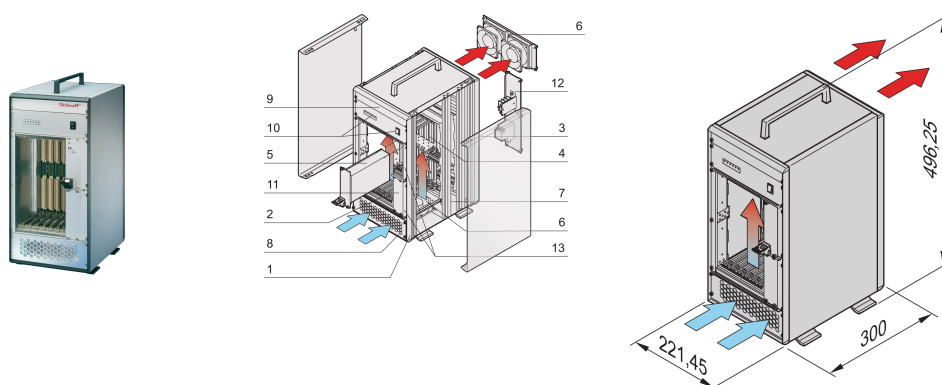

Система Tower для VME64 7 печатных плат VME64x, высота 6 U, 160 мм. Питание системы осуществляется от сменного источника питания. Модуль управления вентилятором контролирует работу вентиляторов, следит за температурой и напряжением.

CERTIFICATIONS



FEATURES

Система в соответствии с IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует требованиям VITA 1.1-1997

сменный источник питания, 19-дюймовый форм-фактор, 250 Вт; дополнительно возможна установка второго блока питания

Отвод тепла 2 вентиляторами, воздушный поток направляется спереди назад; управляется модулем управления вентилятором (FCM) в зависимости от температуры

Система для вертикального крепления печатных плат с учетом формата платы, 6 U, Глубина 160 мм; опция расположения вводов-выводов на задней панели

Модуль индикации рабочего напряжения (пост. ток), аварийные сигналы от вентиляторов и датчиков температуры

Возможность установки 5,25" DVD-дисковод

Backplane VME64x 7 slot, 6 U, J1/J2 monolithic without P0 connector, Rear I/O option, in accordance with VITA 1-1994 and 1.1-1997

PRODUCT ATTRIBUTES

Product Type: System
Number of Slots: 7
Type: Kopnyc Tower
Backplane Type: 6 U VME64 Extension
Data Transfer: VME64; VME2eSST
Power per Slot: 30W
Input Voltage AC: 100 – 240V
Airflow Direction: Front to Rear
Rack Height: 10U
Power Supply Type: (1) Pluggable PSU
Power Supply Included: Да
Rear I/O: Да
Complies With: ANSI/VITA 1.1-1997
Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab Emirates
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	+971.4.378.1700
Chat with us:	Betschdorf, France	Qingdao, China	Bangalore, India
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	+91.80.6715.2001
	Warsaw, Poland	Singapore	Istanbul, Turkey
	+48.22.209.98.35	+65.6768.5800	+90.216.250.7374
	Assago, Italy	Shin-Yokohama, Japan	Chat with us:
	+39.02.932.7141	+81.45.476.0271	nvent.com/schroff
	Chat with us:	Chat with us:	
	nvent.com/schroff	nvent.com/schroff	



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE