
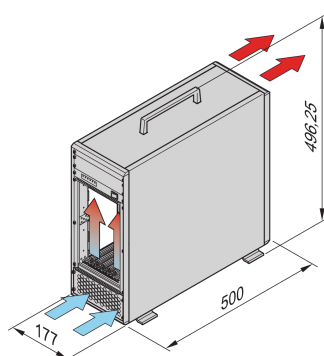


Система VME64x, в корпусе Tower, высота 4 U, блок питания с открытой рамой

CATALOG NUMBER

10836-050

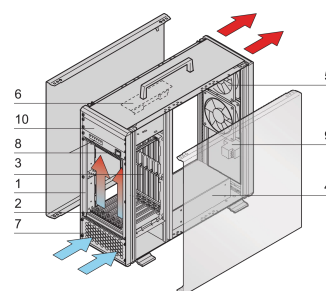

Система VME64 для 7 печатных плат VME64x, высота 6 U, глубина 160 мм. Питание системы осуществляется от источника питания с открытым корпусом. Модуль управления вентилятором контролирует работу вентиляторов, следит за температурой и напряжением.

CERTIFICATIONS



FEATURES

Система в соответствии с IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует требованиям VITA 1.1-1997

Блоки питания, бескорпусного типа, 560 Вт (400 Вт при < 180 В перем.тока)

Отвод тепла 2 вентиляторами, воздушный поток направляется спереди назад; управляется модулем управления вентилятором (FCM) в зависимости от температуры

Система для вертикального крепления печатных плат с учетом формата платы, 6 U, глубина 160 мм

Модуль индикации рабочего напряжения (пост. ток), аварийные сигналы от вентиляторов и датчиков температуры

Возможность установки 5,25" DVD-дисковод

Backplane VME64x 7 slot, 6 U, J1/J2 monolithic without P0 connector, in accordance with VITA 1-1994 and 1.1-1997

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 7

Type: Корпус Tower

Backplane Type: 6 U VME64 Extension

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Input Voltage AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 10U

Power Supply Type: Open Frame

Power Supply Included: Да

Rear I/O: Нет

Complies With: ANSI/VITA 1.1-1997

Глубина мм: 500mm

Высота мм: 496.25mm

Ширина мм: 177mm

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE