


Система PXI с блоком питания ATX, высота 4 U, 8 слотов, ширина 44 HP

CATALOG NUMBER

14579-008

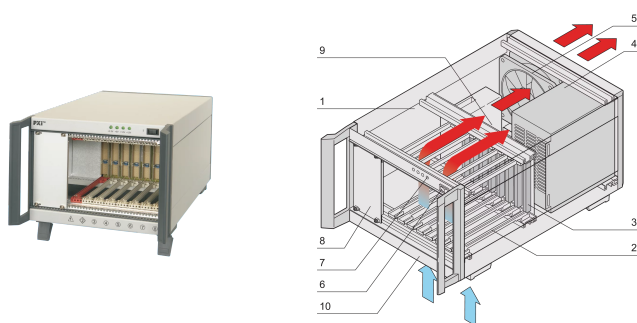

Настольное шасси PXI с вертикальным каркасом для восьми печатных плат 3 U и встроенным источником питания.

CERTIFICATIONS



FEATURES

System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101,10/11); Объединительная плата, соответствует PICMG 3.0 или PXI 2.0

Настольный корпус PXI, 4 U, 44 HP с вертикальным каркасом для печатных плат. Фронтальная плата: 3 U, 160 мм

Объединительная плата, 8 слотов, 3 HE, 64 -разрядная, системный слот слева

Рассеивание тепла с воздушным потоком снизу вверх к задней стороне

Источник питания ATX, 400 Вт, Широкополосный вход переменного тока с выключателем питания на задней панели

Объединительная плата с переключением тактовых сигналов, внутренняя/внешняя

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 8

Type: Настольный корпус

Backplane Type: 3 U CompactPCI with PXIbus

Data Transfer: 64-bit PCI Bus

Power per Slot: 30W

Input Voltage AC: 100 – 240V

Airflow Direction: Bottom to Rear

Rack Height: 4U

Power Supply Type: Open Frame

Power Supply Included: Да

Rear I/O: Нет

Complies With: PXISA PXI-1 R2.0

Глубина мм: 355mm

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE