


Interscale с кондуктивным охлаждением для Embedded NUC, 44 x 112 x 107 мм

CATALOG NUMBER

14830-002

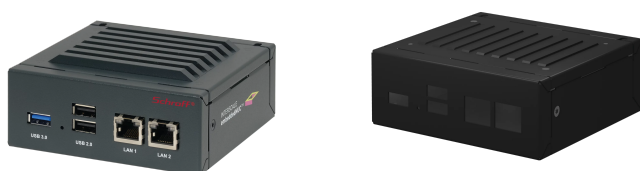

Компактный корпус Small Form Factor с интегрированной системой защиты от электромагнитных помех и кондуктивным охлаждением для плат eNUC, спроектированный на базе инновационной и гибкой платформы nVent SCHROFF Interscale.

CERTIFICATIONS



FEATURES

Корпус модульной конструкции, состоящий из 3 частей (собственно корпуса, верхней крышки и передней панели), простая сборка

Соответствие стандарту SDT.03 embeddedNUC <http://www.sget.org/standards.html>

Специальные вырезы под печатные платы NUC IES MB95 (<http://en.ies.de/>)

Встроенная защита от ЭМС

Встроенный радиатор на верхней крышке с 5-миллиметровыми ребрами теплоотвода

Прочная конструкция, требующая всего двух винтов

Цвет RAL 7016

Установленные шпильки для крепления печатных плат

Доступны другие размеры, формы, размещение вырезов, и трафаретная печать

PRODUCT ATTRIBUTES

Product Type: Small Form Factor Case

Product Family: Interscale

Тип: Настольный корпус

Высота мм: 43.7mm

Ширина мм: 112mm

Глубина мм: 106.5mm

Material: Алюминий

Color: Anthracite Grey

Color Code: RAL 7016

Finish: Powder Coated

Protection Rating: IP20

Cooling: Conduction Cooled

Package Quantity: 1

Net Weight: 0.3kg

ADDITIONAL PRODUCT DETAILS

Совместимы только указанные принадлежности Interscale.

Модифицированные или изготавливаемые по спецификации заказчика корпуса доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE