


Дверной контактный выключатель без кабеля

CATALOG NUMBER

20118-810

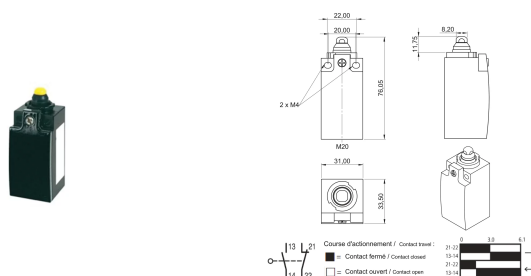

Дверной контактный выключатель с магнитным контактом обеспечивает эксплуатационную эффективность. Это изделие легко подключается по принципу «подключи и работай».

CERTIFICATIONS



FEATURES

Переключатель контактов двери (без соединительного кабеля)

PRODUCT ATTRIBUTES

Product Type: Выключатель

Глубина мм: 33.5mm

Высота мм: 76.5mm

Operating Temperature: -25 to 75°C

Protection Rating: IP66

Ширина мм: 31mm

Complies With: UL® 508; EN 50047 form B

Current Rating: 3 – 6A

Gross Weight: 0.1kg

Package Quantity: 1

Voltage: 24 – 230V

Wire Size: 0.5 – 2.5mm²

ADDITIONAL PRODUCT DETAILS

Кронштейн для установки дверного выключателя (Varistar, Novastar, Eurorack) заказывается отдельно.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE