


# Система VME, высота 8 U, 21 слотов, бескорпусный источник питания

## CATALOG NUMBER

**20836-815**

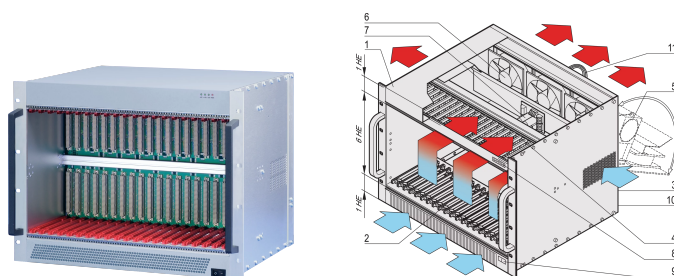

Система VME для 21 печатных плат VME 6 U, 160 мм. Питание системы осуществляется от бескорпусного источника питания. Модуль управления вентилятором контролирует работу вентиляторов, следит за температурой и напряжением.

## CERTIFICATIONS



## FEATURES

Система в соответствии с IEC60297-3-101, -102, -103 IEEE 1101.1, 1101.10/11; объединительная плата соответствует требованиям VITA 1.1-1994

Объединительная плата VME – 21 слот, 6 U, J1/J2, монолитная

Блоки питания, бескорпусного типа, 744 Вт (600 Вт при < 180 В перем. тока)

Отвод тепла 3 вентиляторами, воздушный поток направляется спереди назад; управление температурой с помощью модуля управления вентилятором (FCM)

Модуль индикации рабочего напряжения (пост. ток), аварийные сигналы от вентиляторов и датчиков температуры

Система для вертикального крепления печатных плат с учетом форматов плат; Спереди: 6 U, глубина 160 мм; Сзади: 6 U, 12 HP, глубина 80 мм; для интерфейсных модулей

## PRODUCT ATTRIBUTES

---

Product Type: System

Number of Slots: 21

Type: 19" Rack Mount

Backplane Type: 6 U VME64

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Input Voltage AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 8U

Power Supply Type: Open Frame

Power Supply Included: Да

Rear I/O: Да

Complies With: ANSI/VITA 1.1-1994

Глубина мм: 355mm

Высота мм: 354.8mm

Ширина мм: 449mm

Мощность W: 600W

Net Weight: 17.72kg

Package Quantity: 1

## ADDITIONAL PRODUCT DETAILS

---

Модифицированные системы доступны по запросу.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**