


**Передняя панель для высокочастотного
вставного модуля рамного типа, ЕМС
экранирование со стальной прокладкой, 3 U,
10 НР**

CATALOG NUMBER

20838-094

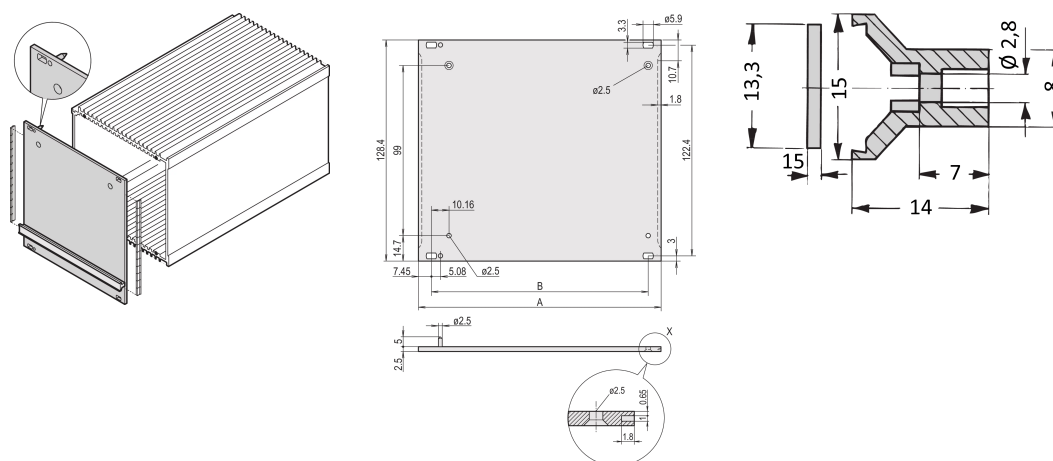

Алюминий, 2,5 мм, передний анодированный, задний проводящий, с боковыми слотами для ЭМС-прокладки из нержавеющей стали (заказывается отдельно), запрессованный центрирующий штифт; ручка трапецевидной формы, серая, PPE, UL 94 V-1.

CERTIFICATIONS



FEATURES

алюминий, 2,5 мм, лицевая поверхность анодированная, тыльная поверхность электропроводящая, с боковыми отверстиями для прокладки из нержавеющей стали ЭМС (заказывайте отдельно), pressed-in alignment pin; trapezium shaped handle, серый, ПФЭ, UL 94 V-1

Передняя панель с ручкой для крепления к высокочастотному сменному блоку

Rack Width: 10HP
Package Quantity: 1
Finish: Anodized; Passivated
Material: Алюминий
Product Type: Side Panel
Rack Height: 3U
Type: Передняя панель
Net Weight: 0.05kg

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

Shieldable, slotted for EMC stainless steel gasket
10, 12, 14, 21, 28 HP

Shieldable, slotted for EMC stainless steel gasket
7 HP

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE