


# Передняя панель, модернизированное экранирование, высота 3 U, ширина стойки 63 HP

CATALOG NUMBER

**20848-068**

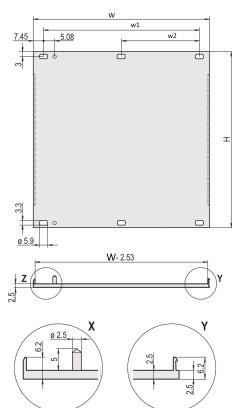

## Текстильный ЭМС-уплотнитель для передней панели

## CERTIFICATIONS



## FEATURES

U-образный профиль, передняя панель, алюминий, 2,5 мм, лицевая поверхность анодированная, тыльная поверхность электропроводящая

Для текстильного уплотнителя ЭМС

## PRODUCT ATTRIBUTES

Rack Height: 3U

Rack Width: 63HP

Package Quantity: 1

Аксессуар Тип: Передняя панель

Mounting: Screw-on Front

Gasket Type: Textile EMC

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Нет

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Глубина мм (D): 2.5mm

EMC Shielding: No (Retrofittable)

Finish: Anodized; Passivated

Высота мм (H): 128.4mm

Material: Алюминий

Product Type: Передняя панель

Type: Front Panel without Handle

Ширина мм (W): 319.7mm

Net Weight: 0.307kg

## ADDITIONAL PRODUCT DETAILS

Крепежный материал (втулки, винты с проточкой) заказывается отдельно.

Есть разница в покрытии между 2 ... 12 HP и 14 ... 84 HP.


от 2 до 12 HP: цельный U-образный профиль

Текстильная ЭМС-прокладка заказывается отдельно.

Standard pack quantity: 2 to 28HP: 5 шт., 42 to 84 HP: 1 шт., supplied in standard pack quantities (SPQ) only.

14 ... 84 HP: multi-part U-profile (front panel with crimped profiles).

## DIAGRAMS

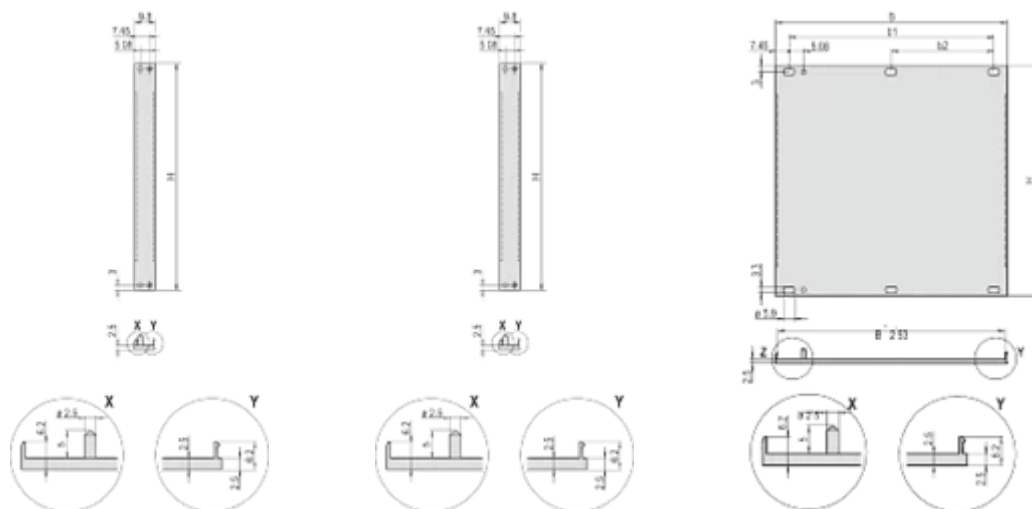

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**