 

 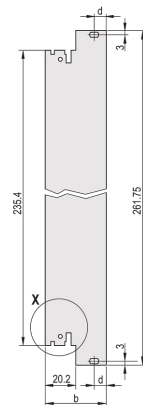

 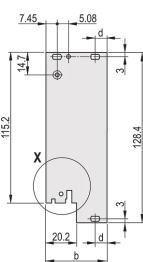

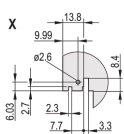
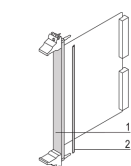
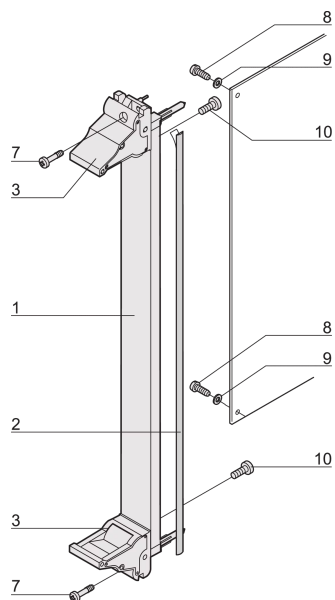


# Комплект сменных модулей с ручкой IEL, экранированный, черный, высота 6 U, ширина стойки 4 HP

 
CATALOG NUMBER

---

**20848-592**

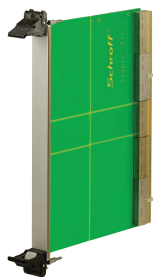

4 TE



5 TE

Сменный модуль, с черной ручкой IEL для вставки/извлечения, 6 U, монтаж спереди. U-образная передняя панель обеспечивает экранирование с помощью текстильного уплотнителя.

## CERTIFICATIONS



FEATURES

- U-образная передняя панель для текстильного уплотнителя
- Подходит для нагрузок вставки и извлечения до 700 Н (на пару ручек)
- Позволяет выполнить установку микропереключателя
- Позволяет выполнить установку кодированных штекеров в соответствии с IEC 60297-3-103/ IEEE 1101.10

PRODUCT ATTRIBUTES

- Rack Width: 4HP
- Package Quantity: 1
- Handle Type: IEL
- Mounting: Screw-on Front; Screw-on Rear IO
- Gasket Type: Textile EMC
- Front Finish: Anodized
- Rear Finish: Etched
- Treated Edges: Нет
- Complies With: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11
- EMC Shielding: Да
- Finish: Anodized; Passivated
- Высота мм (H): 261.8mm
- Material: Алюминий
- Product Type: Передняя панель
- Rack Height: 6U
- Type: Front Panel with Handle (PIU)
- Ширина мм (W): 20mm
- Net Weight: 0.105kg

DIAGRAMS



**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**