 
 

 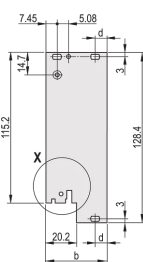

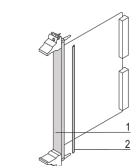



**Комплект сменных модулей с ручкой IEL,
экранированный, черный, высота 6 U,
ширина стойки 12 HP**

CATALOG NUMBER

20848-598

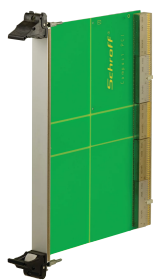

 4 TE



5 TE

Сменный модуль, с черной ручкой IEL для вставки/извлечения, 6 U, монтаж спереди. U-образная передняя панель обеспечивает экранирование с помощью текстильного уплотнителя.

CERTIFICATIONS



FEATURES

- U-образная передняя панель для текстильного уплотнителя
- Подходит для нагрузок вставки и извлечения до 700 Н (на пару ручек)
- Позволяет выполнить установку микропереключателя
- Позволяет выполнить установку кодированных штекеров в соответствии с IEC 60297-3-103/ IEEE 1101.10

PRODUCT ATTRIBUTES

- Rack Width: 12HP
- Package Quantity: 1
- Handle Type: IEL
- Mounting: Screw-on Front; Screw-on Rear IO
- Gasket Type: Textile EMC
- Front Finish: Anodized
- Rear Finish: Etched
- Treated Edges: Нет
- Complies With: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11
- EMC Shielding: Да
- Finish: Anodized; Passivated
- Высота мм (H): 261.8mm
- Material: Алюминий
- Product Type: Передняя панель
- Rack Height: 6U
- Type: Front Panel with Handle (PIU)
- Ширина мм (W): 60.6mm
- Net Weight: 0.206kg

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE