


Задняя панель для RatiорасPRO/PropacPRO, перфорированная, модернизация экранирования, текстиль, 6 U, 42 HP

CATALOG NUMBER

20848-641

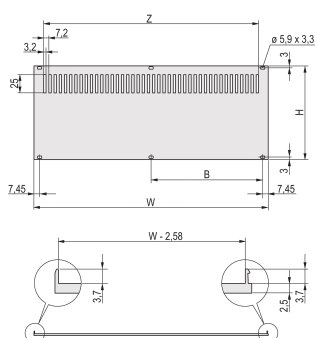

Перфорированная задняя панель, Al, 2,5 мм, без экранирования. Задняя сторона проводящая.

CERTIFICATIONS



FEATURES

Задняя панель, алюминий, 2,5 мм, лицевая поверхность: анодирование, тыльная поверхность: токопроводящая; неэкранированная

Позволяет выполнять монтаж на горизонтальных рейках

PRODUCT ATTRIBUTES

Rack Height: 6U

Rack Width: 42HP

Package Quantity: 1

Finish: Anodized; Passivated

Высота мм: 256mm

Material: Алюминий

Product Family: RatiopacPRO; RatiopacPRO AIR

Product Type: Side Panel

Type: Rear Panel

Ширина мм: 213mm

Works With: Coffrets

Gross Weight: 0.399kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE