


# Дефлектор, передняя панель, модернизированное экранирование, стальной, высота 6 U, ширина стойки 4 HP, 220 мм

## CATALOG NUMBER

**20848-721**

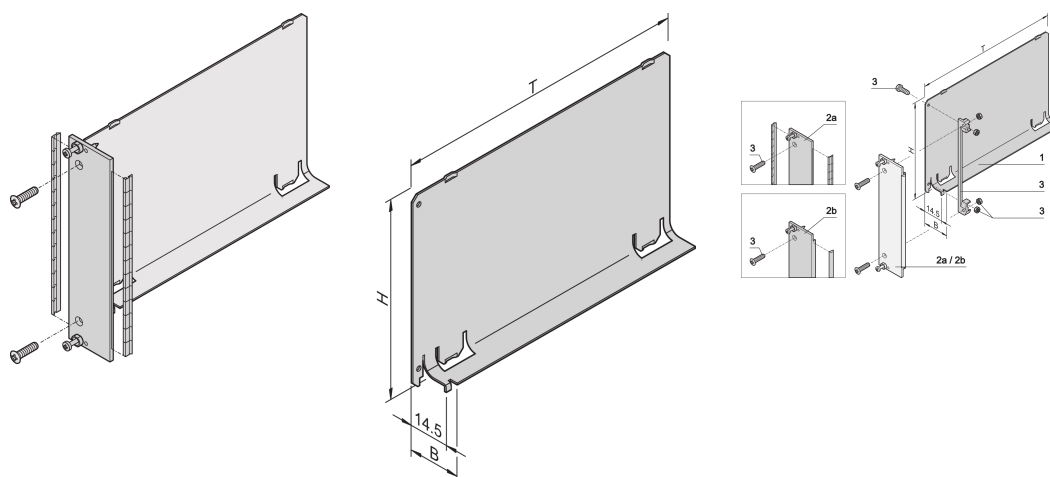

Дефлектор с плоской передней панелью закрывает пустой слот и устраняет утечку воздуха. К плоской передней панели подходит ЭМС-прокладка из нержавеющей стали.

## CERTIFICATIONS



## FEATURES

Дефлекторы исключают утечку воздуха из пустых слотов

Крышка вставляется в направляющую

PRODUCT ATTRIBUTES

|                                                                                       |
|---------------------------------------------------------------------------------------|
| Rack Height: 6U                                                                       |
| Package Quantity: 1                                                                   |
| Глубина мм: 220mm                                                                     |
| EMC Shielding: No (Retrofittable)                                                     |
| Finish: Anodized; Passivated                                                          |
| Material: Алюминий                                                                    |
| Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac |
| Product Type: Air Baffle                                                              |
| Rack Width: 4HP                                                                       |
| Type: With Front Panel                                                                |
| Works With: Блочный каркас; Coffrets                                                  |
| Net Weight: 0.13kg                                                                    |

ADDITIONAL PRODUCT DETAILS

Дефлекторы для плат глубиной 280 мм и для задних плат ввода/вывода глубиной 80 мм доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE