


Фиксатор на четверть оборота с головкой с рифлением и шлицем, серый

CATALOG NUMBER

21101-849

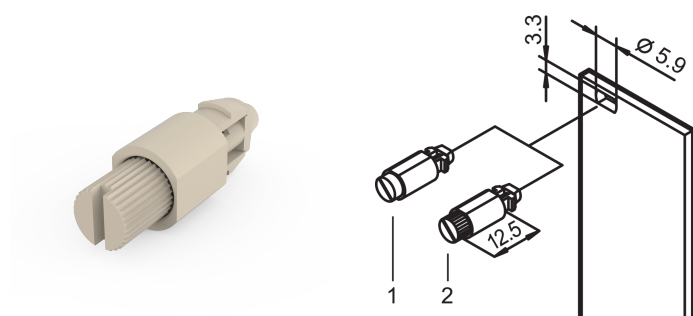

1/4 поворотный замок с фиксированным упором.

CERTIFICATIONS



FEATURES

Замыкание оборотом на 1/4 поворота с фиксированным упором

Распознавание положения запираения по положению шлица

Устойчивость к вибрациям и сотрясениям

Кол-во 100 шт.

PRODUCT ATTRIBUTES

Color: Pebble Grey

Package Quantity: 100

Color Code: RAL 7032

Глубина мм: 20.6mm

Finish: Nickel Plated

Высота мм: 6mm

Material: Сталь; Zinc Alloy; Thermoplastic

Product Type: Hardware Kit

Ширина мм: 7mm

Works With: Передние панели

Fastener Type: Knurled; Slotted Head

Net Weight: 0.15kg

ADDITIONAL PRODUCT DETAILS

Быстроразъемные фиксаторы: монтаж без резьбовых вставок.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE