


Мост CPCI, 32-разрядный, 33 МГц

CATALOG NUMBER

23006-920

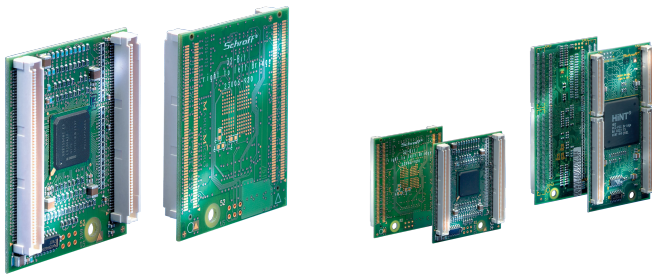

Очень компактная и низкая форма моста, без взаимных помех с платами Rear Transition.

CERTIFICATIONS



FEATURES

Мост предназначен для основных объединительных плат с системным слотом справа; мост для системного слота слева доступен по запросу

До 33 МГц

Мост устанавливается на обратной стороне объединительной платы, что не приводит к потере слотов

В соответствии с: спецификация мостов PICMG 2.6 CompactPCI, спецификация локальной шины PCI 2,1 PCI, ред. 2,1

PRODUCT ATTRIBUTES

Product Type: Объединительная плата

Backplane Type: CompactPCI Bridge, 32-bit, 33 MHz

System Slot: Right

Net Weight: 0.028kg

Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE