


Комплект для комбинированного монтажа для шасси, ширина стойки 84:0 HP

CATALOG NUMBER

24562-484

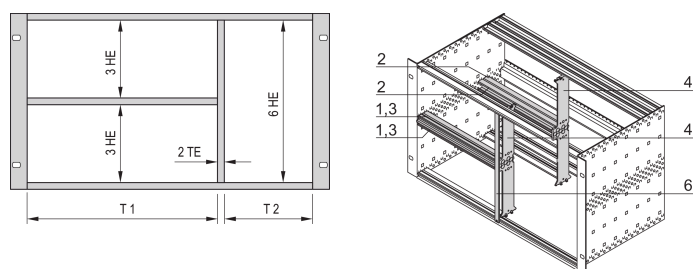

Комбинированный монтаж позволяет разделить блочный каркас или корпус высотой 6 U на секции 2 x 3 U и 6 U. Доступны различные варианты.

CERTIFICATIONS



FEATURES

Для стандартных европлат (высотой 100 мм) и для европлат двойной высоты (высотой 233,35 мм)

Монтажное пространство высотой 6 U разделено на секции: 2 x 3 U, 1 x 6 U

PRODUCT ATTRIBUTES

Package Quantity: 1

Rack Width 1: 84HP

Material: Алюминий; Zinc Alloy

Product Family: EuropacPRO

Product Type: Mounting Kit

Rack Height: 6U

Type: Combined

Works With: Блочный каркас

Net Weight: 0.657kg

ADDITIONAL PRODUCT DETAILS

Please order separately: Передняя панель 6 U, 2 HP to cover the strut.

The following guide rails cannot be used: type "accessory", type "accessory, strengthened" and type "for 4,4" PCB".

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE