


Передняя панель EuropacPRO для 19-дюймового распределительного модуля, высота 3 U, ширина стойки 84 HP

CATALOG NUMBER

24563-096

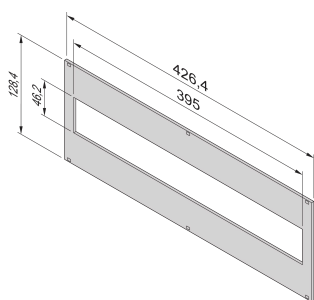

Передняя панель с вырезом соответствует DIN 43880 (для модулей распределения питания).

CERTIFICATIONS



FEATURES

Передняя панель с вырезом соответствует DIN 43880 (для модулей распределения питания)

Высота 3 U, ширина 84 HP

PRODUCT ATTRIBUTES

Product Type: Передняя панель

Product Family: EuropacPRO

Аксессуар Тип: Передняя панель

Mounting: Screw-on Front

Material: Алюминий

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Het

Rack Height: 3U

Высота мм: 128.4mm

Rack Width: 84HP

Ширина мм: 426.4mm

Глубина мм: 2.5mm

Package Quantity: 1

Finish: Anodized; Passivated

Net Weight: 0.38kg

ADDITIONAL PRODUCT DETAILS

В комплект поставки включены 2 пластмассовые защитные планки для крышки.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE