


Комплект для блочного каркаса EuroPacPRO для модуля распределения электропитания, неэкранированный, 3 U, 84 HP, 115 мм

CATALOG NUMBER

24563-100

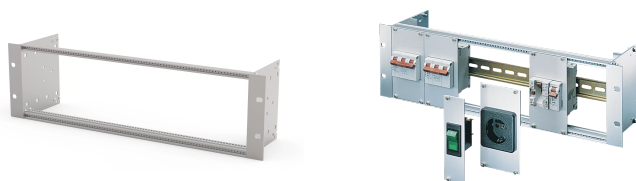

Для монтажа установочных устройств в соответствии с DIN 43880 размером 1-3 с технологией защелкивания, например монтажные гнезда, автоматические выключатели или выключатели остаточных токов. Они могут быть установлены после установки горизонтального рельса с кромкой DIN-центрального рельса (35/7,5)

CERTIFICATIONS



FEATURES

Для монтажа установочных устройств в соответствии с DIN 43880 размером 1-3 с технологией защелкивания, например монтажные гнезда, автоматические выключатели или выключатели остаточных токов. Они могут быть установлены после установки горизонтальных рельсов с кромкой DIN-центрального рельса (35/7,5)

Модульная рама для размещения, например модулей распределения питания

Внутренние и внешние размеры в соответствии со стандартами IEC 60297-3-101 и IEEE 1101.1

Алюминиевые боковые панели

Horizontal rails type "light"

PRODUCT ATTRIBUTES

Product Type: Subrack/Chassis

Rack Height: 3U

Rack Width: 84HP

Глубина мм: 115mm

For Mounting: Power Distribution Module

EMC Shielding: Нет

Static Load: 2.5kg

Handle Included: Нет

Mounting: Rack

Complies With: IEC 60297-3-103

Package Quantity: 1

Finish: Anodized; Passivated

Высота мм: 132.55mm

Material: Алюминий

Ширина мм: 482.6mm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE