


EuropacPRO Advanced EMC Side Panel Cover, 4U, 295 mm

CATALOG NUMBER

24563-267

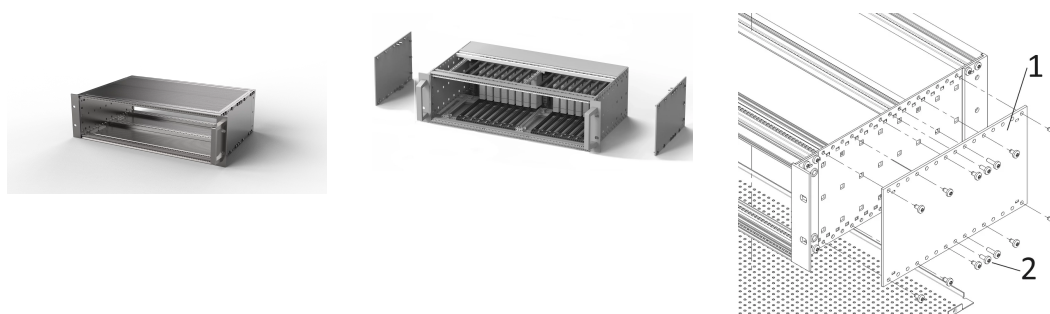

Aluminium Side panel 3mm to increase the EMC shielding effect of the subrack by covering the not needed cut-outs.

CERTIFICATIONS



FEATURES

Side panel covers for increased lateral RF shielding

Assembled on the outside of the standard side panel

Assembly material included

PRODUCT ATTRIBUTES

Rack Height: 4U

Глубина мм: 295mm

Package Quantity: 2

EMC Shielding: Да

Finish: Passivated

Длина мм: 295mm

Material: Алюминий

Product Family: EuropacPRO

Product Type: Side Panel

Type: Type H

Works With: Блочный каркас

Package Unit: Pair

ADDITIONAL PRODUCT DETAILS

Side panel and 19" bracket are tox-cold welded together. toxen = Clinching technique, without add aids. This takes place with special tools and high pressure.

9 U version available on request.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE