


Кожух для поддержки модуля на 19 дюймов

CATALOG NUMBER

24564-100

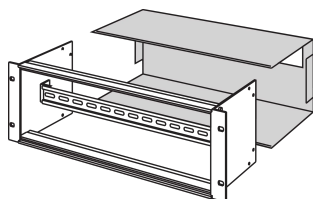

Капот, закрывающий заднюю сторону опоры модуля на 19 дюймов.

CERTIFICATIONS



FEATURES

Для сборки на опоре 19-дюймового модуля

Rear cut out for cable entry (351 x 40mm) cover through two brush strips

Rear hood prepared for grounding kit

Brush strip (self-adhesive): Plastic PVC (RAL7032), Bristle: Nylon black

PRODUCT ATTRIBUTES

Product Type: Крышка

Product Family: EuropacPRO

Type: Rear Hood

Works With: Блочный каркас

Rack Height: 3U

Высота мм: 132.5mm

Rack Width: 84HP

Ширина мм: 431.5mm

Глубина мм: 88.3mm

Material: Алюминий

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE