


Передняя рама для ЭМС-экранирования для монтажа горизонтальных печатных плат, высота 3 U, ширина стойки 20 HP

CATALOG NUMBER

24564-109

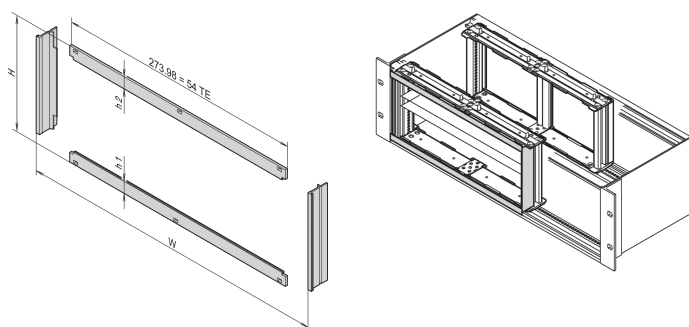

Установка передней рамы обеспечивает контакт между блочными каркасами и узлами. Она должна использоваться, если заказчик выбрал комплект для горизонтального монтажа печатной платы.

CERTIFICATIONS



FEATURES

Установка передней рамы обеспечивает контакт между блочными каркасами и узлами

PRODUCT ATTRIBUTES

Rack Height: 3U

Rack Width: 20HP

Package Quantity: 1

Finish: Anodized; Passivated

Material: Алюминий

Product Family: EuropacPRO

Product Type: Side Panel

Works With: Блочный каркас

Net Weight: 0.1kg

ADDITIONAL PRODUCT DETAILS

H=128,40 мм, h1=h2= 13,23 мм

Контактная лента ЭМС, нержавеющая сталь, см. раздел «Подузлы/передние панели».

Принадлежности заказываются отдельно.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE