
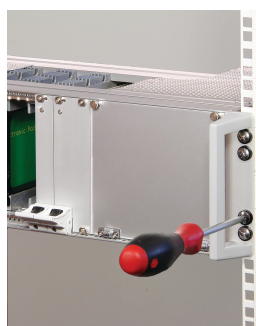


Передняя ручка, для боковых панелей типа R

CATALOG NUMBER

24566-010

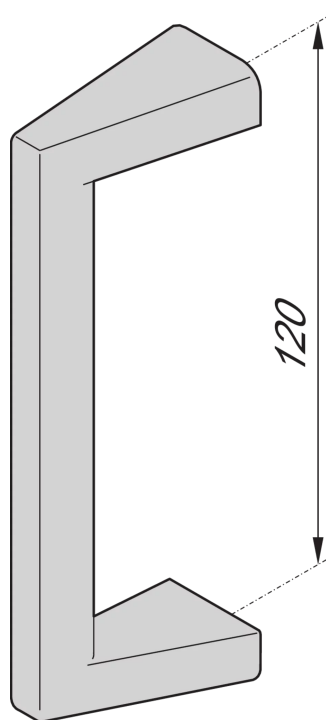

Передняя ручка для блочного каркаса повышенной прочности имеет нагрузочную способность 30 кг. Она оптимизирует монтаж блочного каркаса в шкаф.

CERTIFICATIONS



FEATURES

Допустимая нагрузка 30 кг

Подходит для боковых панелей 3 и 6 U

Форма ручки облегчает сборку крепежных винтов M6

PRODUCT ATTRIBUTES

Product Type: Ручка
Works With: Блочный каркас
Handle Type: Straight
Ширина мм: 12.2mm
Material: Алюминий
Color: Серебристый
Package Quantity: 2
Глубина мм: 40mm
Finish: Powder Coated
Torque: 2.4N·m

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE